


NOTES:

- 1. RoHS: EXEMPT

 
**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

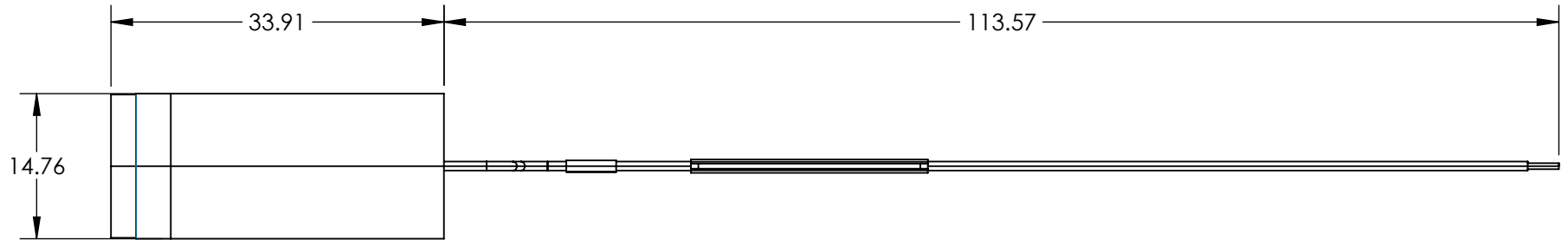

	VALUE
DESIGN WAVELENGTH (nm)	635.0
OUTPUT POWER (mW)	4.90
BEAM DIAMETER (mm)	1.1 @ MODULE FACE
COLOR	RED
LASER CLASS - CDRH	IIIa
POINTING ACCURACY (mrad)	<4
POWER REQUIREMENT	5-10V DC
TYPE	DIODE

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY



THIRD ANGLE PROJECTION 

ALL DIMS IN mm

TITLE	COHERENT® VHK™ CIRCULAR BEAM VISIBLE LASER DIODE 0221-700-01   4.9mW 635nm
DWG NO	54025
	SHEET 1 OF 1